


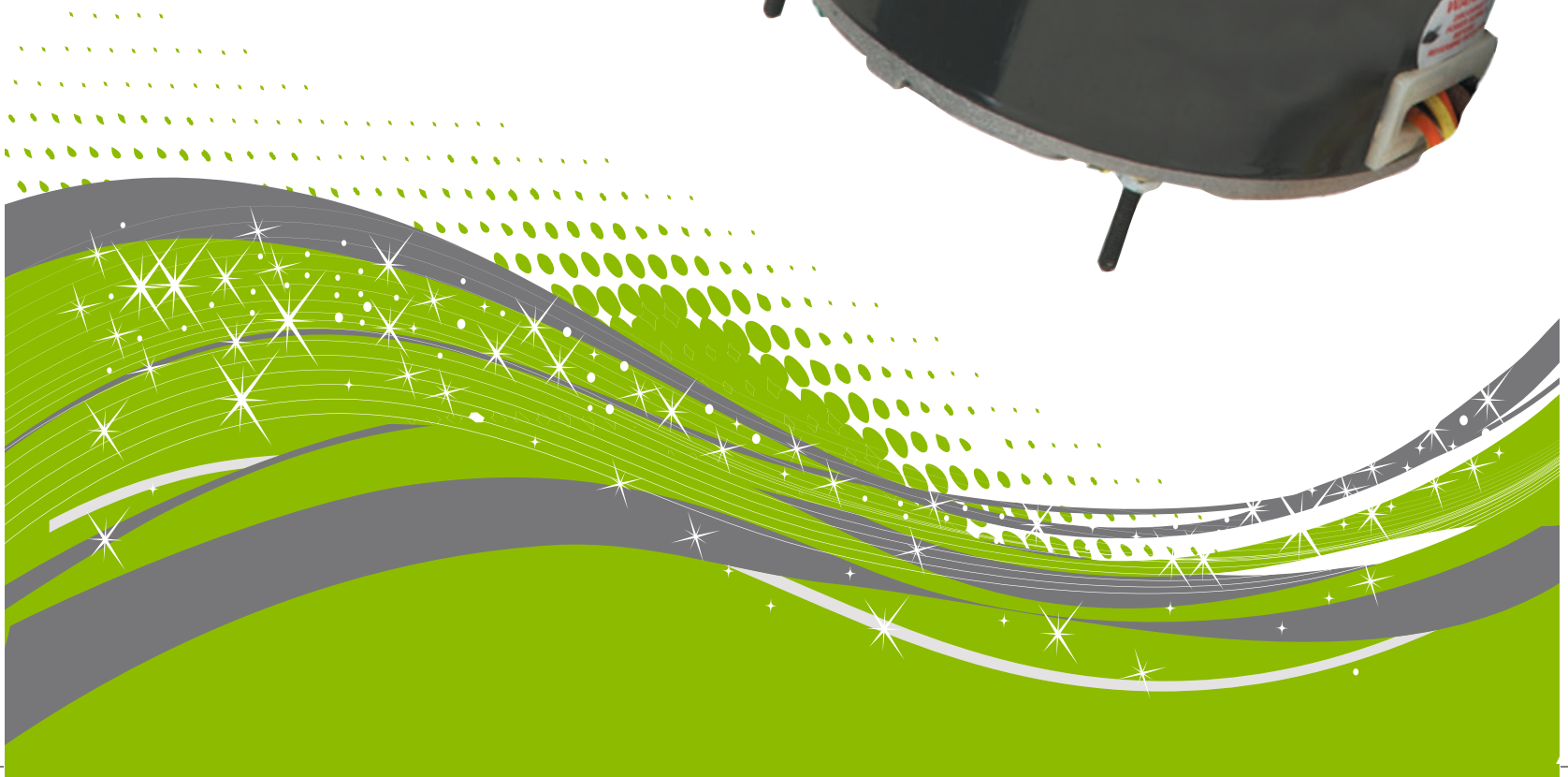

The SF™ Motor Advantage

- Options for working on competitors equipment
- Economical truck stock motors
- Quality product at value pricing
- For you and your customers who want options that offer simple value solutions



CONDENSER FAN MOTORS

- 140 degree ambient
- Totally Enclosed Air Over
- HP 1/6-3/4
- Sleeve Bearings
- Use with 370v Capacitor
- Continuous Duty

CONDENSER FAN TEAO				
HP	VOLTAGE	SPEED	BEARING	SF MOTOR
1/6	208/230	1075/1	SLEEVE	SFMC161SP2V
1/4	208/230	1075/1	SLEEVE	SFMC251SP2V
1/3	208/230	1075/1	SLEEVE	SFMC331SP2V
1/2	208/230	1075/1	SLEEVE	SFMC501SP2V
3/4	208/230	1075/1	SLEEVE	SFMC751SP2V
1/6	208/230	825/1	SLEEVE	SFMC161SP2V8 (soon)
1/4	208/230	825/1	SLEEVE	SFMC251SP2V8 (soon)
1/3	208/230	825/1	SLEEVE	SFMC331SP2V8 (soon)

BLOWER MOTORS

- Open Air Over
- Use with 370v Capacitor
- HP ¼-3/4
- Voltage options for both 115v or 208-230v
- Standard 1075 RPM

BLOWER OAO				
HP	VOLTAGE	SPEED	BEARING	SF MOTOR
1/4	115	1075/3	SLEEVE	SFMB253SP1V
1/3	115	1075/3	SLEEVE	SFMB333SP1V
1/2	115	1075/3	SLEEVE	SFMB503SP1V
3/4	115	1075/3	SLEEVE	SFMB753SP1V
1/4	208/230	1075/3	SLEEVE	SFMB253SP2V
1/3	208/230	1075/3	SLEEVE	SFMB333SP2V
1/2	208/230	1075/3	SLEEVE	SFMB503SP2V
3/4	208/230	1075/3	SLEEVE	SFMB753SP2V

MULTIPLE HORSE POWER MOTORS

- Condenser fan and direct drive blower motor applications
- Great for replacing a variety of horse power motors
- Have a motor available that covers HP ranges of 1/6-3/4
- Limit the amount of sku's needed on your truck

MULTIPLE HORSE POWER				
TYPE	HP	VOLTAGE	SPEED	SF MOTOR
CFM	1/6-1/3	208/230	1075	SFMMH332V
CFM	1/6-1/3	208/230	825	SFMMH332V8
CFM	1/5-1/2	208/230	1075	SFMMH502V
DDB	1/5-3/4	208/230	1075	SFMMH752VB
DDB	1/6-1/2	208/230	1075	SFMMH502VB
DDB	1/5-3/4	115	1075	SFMMH751VB
DDB	1/6-1/2	115	1075	SFMMH501VB

